

MODEL 143MR

Current Transformer with Multi-Ratio

Window Diameter 7.31"



Application

Relaying.

Frequency

50-400 Hz

Insulation Level

600 Volt, 10 kV BIL full wave.

Continuous Thermal Current Rating Factor

Terminals are brass screws No. 10-32 with one flatwasher and lockwasher.

The transformer winding is arranged so that the turns are fully distributed between all taps.


Order mounting bracket kit 0221B00775 separately.

Approximate weight 60 lbs.

Model 143MR

| CATALOG NUMBER | RELAY CLASS | CONTINUOUS THERMAL RATING FACTOR | |
|----------------|-------------|----------------------------------|--------|
| | | @30°C | @ 55°C |
| 143-601MR | C200 | 2.0 | 1.5 |
| 143-122MR | C400 | 1.5 | 1.0 |
| 143-202MR | C400 | 1.33 | 1.0 |
| 143-302MR | C800 | 1.0 | 0.8 |
| 143-402MR | C800 | 1.0 | 0.6 |
| 143-502MR | C800 | 1.0 | 0.6 |

Excitation Data Available Upon Request

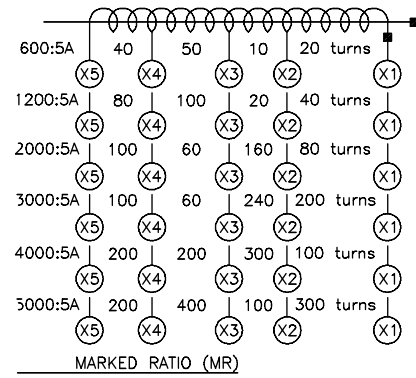

GEA-N50461
English
251013