

NUMBER: 05-6172A01, Rev. B
November 2025

*Applies to Manual
Part No. 05-4161A01*

GE Vernova MDS, LLC., 175 Science Parkway, Rochester, NY 14620
USA Phone +1 (585) 242-9600

APPROVED POWER SUPPLY CONFIGURATIONS For MDS SD4P with CE Mark and “Power Supply Safety”


INTRODUCTION

The SD4P, when ordered in the CE mark configuration, is approved in the following power supply configurations:

- 24-48 Vdc @ 2.5 Amperes maximum
DC internal resettable fuses are rated at 6 Amperes
CAUTION: Double Pole/Neutral Fusing
- 115/230 Vac @ 1.7 Amperes maximum
AC replaceable fuse is rated at 3 Amperes

See rear panel of the SD4P for power supply input connections. On the rear of the unit there is a wiring terminal intended for connection of a protective Earth ground.

Before servicing, ensure that all AC or DC power is removed from the unit.

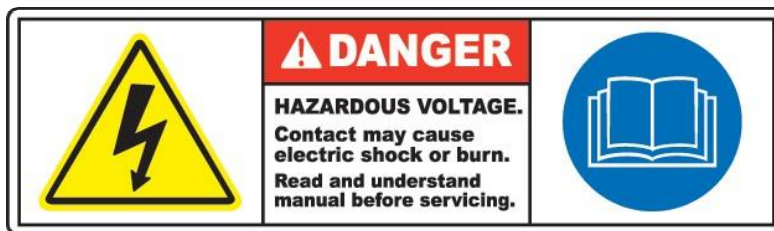

If you have any further questions regarding this matter, please contact your Sales representative or GE MDS Technical Services at (585) 241-5510.

End of Addendum