



GE Energy Storage Reservoir Inverter Unit

Modular, Scalable Energy Storage Inverter for Utility-Scale Applications


Reservoir Inverter Unit Data

SPECIFICATIONS	UNITS	RIU-2500
AC Parameters		
Nominal Power (at 45°C)	kVA _{AC}	2500
Max Power (at 40°C)	kVA	2750
Rated AC Operating Voltage (10-35kV)	V _{AC}	550
AC Operating Voltage Range	%	+ / - 10
Grid Frequency (+/-5 Hz)	Hz	50 / 60
Power Factor Range		-1.0 to 1.0
DC Parameters		
DC Input Range	V _{DC}	800-1500
Max DC Current	A	3508
Operational Parameters		
Max Efficiency	%	98.73
CEC Efficiency	%	98.50
Power Consumption at Stop	W	370
Max Power Consumption	kW	4.3
Audible Noise (at 1m)	dBA	<80
Physical Parameters		
Dimensions (L x W x H)	mm	6058 X 2438 X 2890
Weight	kg	17000
Ambient Temperature Range	°C	-30 to +50 ¹
Elevation	m	<2500 ²
IP Class / NEMA Rating		IP 54 / NEMA 3R
Cable Entry		Bottom
Communications		
External Standard		RS-485 / Ethernet / FO
Response Time	mSec	<100


SPECIFICATIONS	UNITS	RIU-2500
Equipment		
Ground Fault Monitoring		Yes
AC Circuit Breaker		Yes (Lockable)
Fused DC Load Switch		Yes (Lockable)
Integrated LV Auxiliary Power Supply		Yes
Features		
Anti-islanding		Yes
Reactive Power Compensation		Yes
Low Voltage Ride Through (LVRT)		Yes
High Voltage Ride Through (HVRT)		Yes
Frequency Ride Through		Yes
Certifications & Compliance		
Certifications		UL 1741; IEC 62109
Compliance		SA/Rule 21; IEEE 547; IEC 62477; PRC-024 (Optional); AS300 (Optional); CE Mark

1. Lower ambient temperature -40°C optional with kit
2. Higher altitudes up to 4000m (with derating) on request


2. Temperature Rating

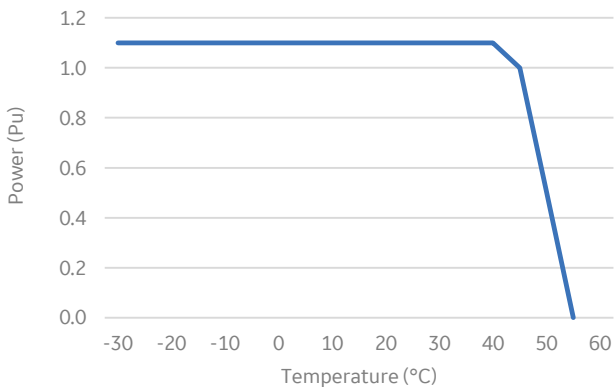

3. Altitude Rating

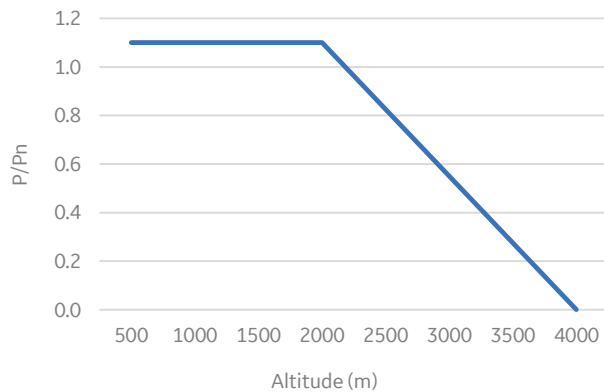

4. Nominal Capability Curve**

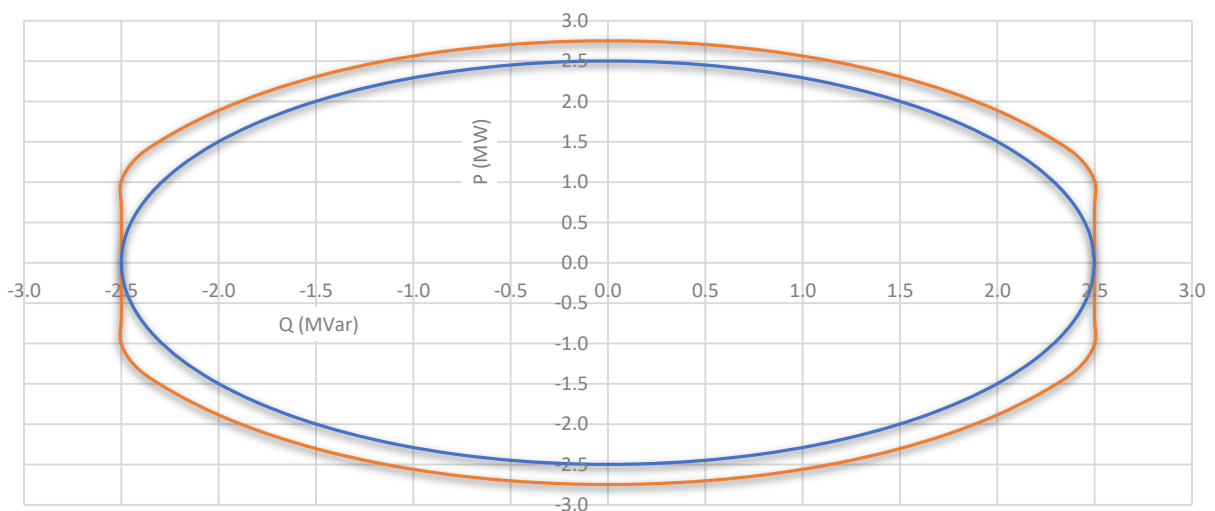

**≤45°C represented in blue; ≤40°C represented in orange

www.ge.com/energystorage

©2020 General Electric. All rights reserved. *Trademark of General Electric. All other brands or names are property of their respective holders. GE reserves the right to make technical changes or modify the contents of this document without prior notice. Agreed particulars within purchase order will prevail.